

**Industriellt Ethernet
IE-TO-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com



Bärskenutgångar, utförande koppling SC-RJ enligt IEC
61754-24

Allmänna beställningsdata

Typ	IE-TO-SCRJ-SM
Art.nr.	8947000000
Artikelbeteckning	Montageskena-utgång FO, SCRJ, Singlemode, IP20
GTIN (EAN)	4032248735013
Frp	10 Stück

**Industriellt Ethernet
IE-TO-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
 Klingenbergstraße 16
 D-32758 Detmold
 Germany
 Fon: +49 5231 14-0
 Fax: +49 5231 14-292083
 www.weidmueller.com

Tekniska data**Mått och vikter**

Nettovikt	38,1 g
-----------	--------

Temperaturer

Driftstemperatur, max	70 °C	Driftstemperatur, min.	-40 °C
Drifttemperatur	-40 °C...70 °C	Lagertemperatur	
Temperaturområde Montage, min.	-25 °C	Installation temperature	
Temperaturområde Montage, max.	70 °C		

Allmänna data

Anslutning 1	SCRJ	Anslutning 2	SCRJ
Dämpning	≤ 0,5 dB	Fibertyp	Singlemode
Färgkod	ljusgrå	Kapslingsmaterial	PA UL 94 V0
Monteringstyp	TS 35	Skyddsklass	IP20
Stickcykler	1000		

Normer

Kontaktdon Norm	IEC 61754-24	Certifikat nr. (UL)	E477798
-----------------	--------------	---------------------	---------

Klassificeringar

ETIM 3.0	EC000018	ETIM 4.0	EC000018
ETIM 5.0	EC000018	ETIM 6.0	EC000313
UNSPSC	30-21-18-01	eClass 6.2	27-25-05-04
eClass 7.1	27-25-05-04	eClass 8.1	19-17-01-25
eClass 9.0	27-44-03-20	eClass 9.1	19-17-01-25

Godkännanden

Godkännanden



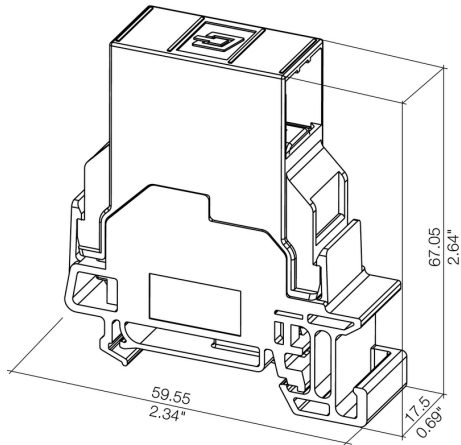
ROHS	Uppfyllelse
------	-------------

Downloads

Användardokumentation	MAN IE GUIDE DE MAN IE GUIDE EN
Broschyr/Katalog	CAT 9 IETH 15/16 EN FL FIELDWIRING EN PI PROFINET CABLING EN
Godkännande/Certifikat/Dokument om överensstämmelse	PROFINET Manufacturer's Declaration

**Industriellt Ethernet
IE-TO-SCRJ-SM**

Weidmüller Interface GmbH & Co. KG
Klingenbergstraße 16
D-32758 Detmold
Germany
Fon: +49 5231 14-0
Fax: +49 5231 14-292083
www.weidmueller.com

Ritningar**Profilritning****Ritning**