

**Industriell Ethernet  
IE-TO-LCD-SM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com



Montageskeneutgång, LC duplex-anslutningsdesign enligt  
IEC 61754-20

**Allmänna beställningsdata**

|                   |                                                     |
|-------------------|-----------------------------------------------------|
| Typ               | IE-TO-LCD-SM                                        |
| Art.nr.           | <a href="#">8947020000</a>                          |
| Artikelbeteckning | Montageskena-utgång FO, LC-Duplex, Singlemode, IP20 |
| GTIN (EAN)        | 4032248735037                                       |
| Frp               | 10 Stück                                            |

**Industriellt Ethernet  
IE-TO-LCD-SM****Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

**Tekniska data****Mått och vikter**

|           |      |
|-----------|------|
| Nettovikt | 35 g |
|-----------|------|

**Temperaturer**

|                                |                |                          |        |
|--------------------------------|----------------|--------------------------|--------|
| Driftstemperatur, max          | 70 °C          | Driftstemperatur, min.   | -40 °C |
| Drifttemperatur                | -40 °C...70 °C | Lagertemperatur          |        |
| Temperaturområde Montage, min. | -25 °C         | Installation temperature |        |
| Temperaturområde Montage, max. | 70 °C          |                          |        |

**Allmänna data**

|               |           |                   |             |
|---------------|-----------|-------------------|-------------|
| Anslutning 1  | LC Duplex | Anslutning 2      | LC Duplex   |
| Dämpning      | ≤ 0,5 dB  | Fibertyp          | Singlemode  |
| Färgkod       | ljusgrå   | Kapslingsmaterial | PA UL 94 V0 |
| Monteringstyp | TS 35     | Skyddsklass       | IP20        |
| Stickcykler   | 1000      |                   |             |

**Normer**

|                  |              |
|------------------|--------------|
| Kontaktidon Norm | IEC 61754-20 |
|------------------|--------------|

**Klassificeringar**

|            |             |            |             |
|------------|-------------|------------|-------------|
| ETIM 3.0   | EC000018    | ETIM 4.0   | EC000018    |
| ETIM 5.0   | EC000018    | ETIM 6.0   | EC000313    |
| UNSPSC     | 30-21-18-01 | eClass 6.2 | 27-25-05-04 |
| eClass 7.1 | 27-25-05-04 | eClass 8.1 | 19-17-01-25 |
| eClass 9.0 | 27-44-03-20 | eClass 9.1 | 19-17-01-25 |

**Godkännanden**

Godkännanden



|      |             |
|------|-------------|
| ROHS | Uppfyllelse |
|------|-------------|

**Downloads**

|                       |                                                                                                                    |
|-----------------------|--------------------------------------------------------------------------------------------------------------------|
| Användardokumentation | <a href="#">MAN IE GUIDE DE</a><br><a href="#">MAN IE GUIDE EN</a>                                                 |
| Broschyr/Katalog      | <a href="#">CAT 9 IETH 15/16 EN</a><br><a href="#">FL FIELDWIRING EN</a><br><a href="#">PI PROFINET CABLING EN</a> |

**Industriellt Ethernet  
IE-TO-LCD-SM****Weidmüller Interface GmbH & Co. KG**

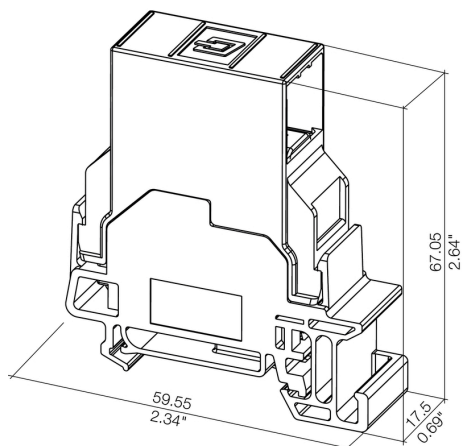
Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

[www.weidmueller.com](http://www.weidmueller.com)**Ritningar****Profilritning****Ritning**