

SAI-ADAPT-M8/M12 4P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

M8/M12- och M12/M8-adaptrar bidrar till snabb implementering av kontaktstorleken.

Allmänna beställningsdata

Typ	SAI-ADAPT-M8/M12 4P
Art.nr.	1990540000
Artikelbeteckning	Y-kontakt, M12 / M8
GTIN (EAN)	4050118376371
Frp	1 Stück

SAI-ADAPT-M8/M12 4P**Weidmüller Interface GmbH & Co. KG**

Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com

Tekniska data**Mått och vikter**

Nettovikt	15 g
-----------	------

Environmental Product Compliance

REACH SVHC	Lead 7439-92-1
------------	----------------

Anslutningsdata

Individuell utgång 1 – kontaktdon	M8 hane	Individuell utgång 2 – kontaktdon	M12 hona
Åtdragningsmoment	M12: 0,8 Nm, M8: 0,5 Nm		

Allmänna data

Anslutningsgंगा	M12 / M8	Antal poler	4
Kodering	M12 = A, M8 = ingen	Ledarytterdiameter	-
Märkspänning	24 V	Märkström	4 A
Nedsmuttningsgrad	3	Skyddsklass	IP67
Temperaturområde kapsling	-25...+85 °C		

Klassificeringar

ETIM 5.0	EC002635	ETIM 6.0	EC002925
eClass 6.2	27-26-07-02	eClass 7.1	27-44-01-02
eClass 8.1	27-44-01-02	eClass 9.0	27-44-01-06
eClass 9.1	27-44-01-06		

Godkännanden

ROHS	Uppfyllelse
------	-------------

Downloads

Broschyr/Katalog	FL FIELDWIRING EN
------------------	-----------------------------------

SAI-ADAPT-M8/M12 4P**Weidmüller Interface GmbH & Co. KG**

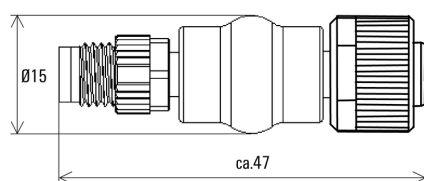
Klingenbergstraße 16

D-32758 Detmold

Germany

Fon: +49 5231 14-0

Fax: +49 5231 14-292083

www.weidmueller.com**Ritningar****Profilritning****Kopplingsbild**