

auxiliary current switch, low power rating 1 NO+1 NC for miniature circuit breaker 5SL, 5SY, 5SP Incorporated switch 5TL1, RCBO 5SU1, FI 5SV (for 5SU1 handle coupler 5ST3805-1 is required)



Versiyon

ürün marka adı	SETRON
ürün tanımı	Yardımcı akım şalteri
ürün modeli	takılabilir
elektrikli işletim süresi (işletim çevrimleri) / tipik	20 000

Besleme gerilimi

işletim gerilimi	
• anma değeri	30 V
IP koruma türü	IP20

Ürün Detayı

ürün bileşeni	
• yardımcı anahtar	Evet
ürün ilavesi	Yardımcı şalter

Numara

hata sinyali anahtarı sayısı	0
açıcı sayısı	1
kapayıcı sayısı	1
değiştirici sayısı	0





Bağlantılar

bağlanabilir kablo kesiti	0,5 ... 2,5 mm ²
sıkma torku / vida bağlantısında	0,5 N·m
bağlanabilir iletken kesit türü / AWG hatlarında	24 ... 12

Mekanik Tasarım

yükseklik	90 mm
genişlik	9 mm
derinlik	70 mm
net ağırlık	66 g
• işletim sırasında	-25 ... +55 °C
• depolama sırasında	-40 ... +75 °C

Sertifikalar

General Product Approval	Declaration of Conformity	Shipping Approval	other	Railway
 UR	 VDE	 EG-Konf.	 LRS	Miscellaneous Vibration and Shock

Diğer bilgiler

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/tr/tr/Catalog/product?mlfb=5ST3013>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/tr/ps/5ST3013>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)



http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3013

CAx-Online-Generator


<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

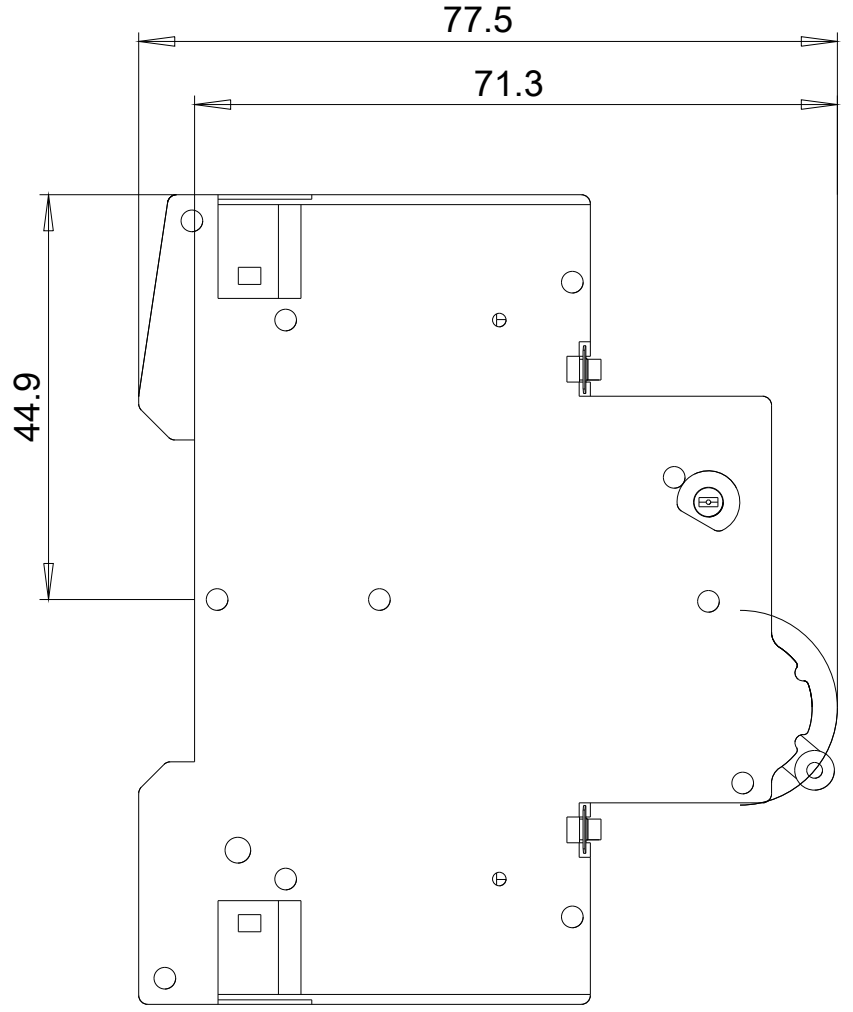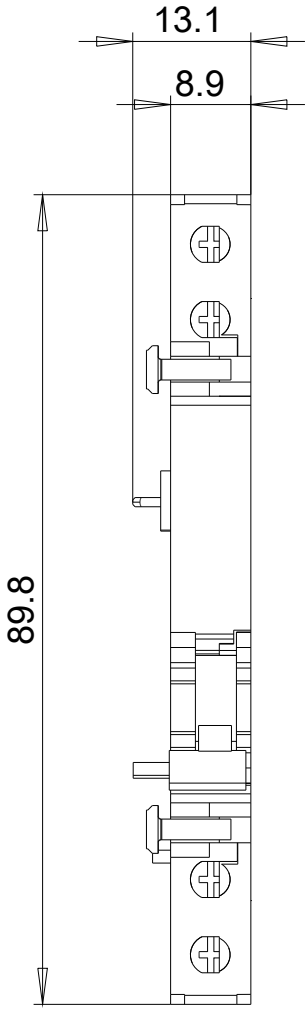

13 21

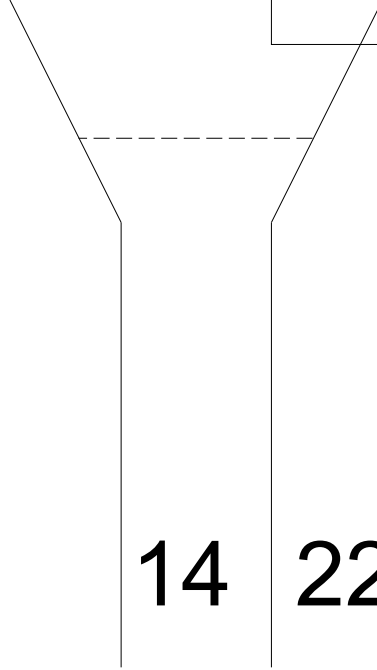

14 22

