

Fault signal contact 1 NO+1 NC, for miniature circuit breaker 5SL, 5SY, 5SP RCBO 5SU1, FI 5SV (for 5SU1 handle coupler 5ST3805-1 is required)



Versiyon	
ürün marka adı	SETRON
ürün tanımı	Hata sinyal anahtarı
ürün modeli	takılabilir
elektrikli işletim süresi (işletim çevrimleri) / tipik	20 000
IP koruma türü	IP20

Ürün Detayı	
ürün bileşeni	
• Hata sinyal şalteri	Evet
ürün ilavesi	Hata sinyal kontağı

Numara	
hata sinyali anahtarı sayısı	1
açıcı sayısı	1
kapayıcı sayısı	1
değiştirici sayısı	0






Bağlantılar	
bağlanabilir kablo kesiti	0,5 ... 2,5 mm <sup>2</sup>
sıkma torku / vida bağlantısında	0,5 N·m

bağlanabilir iletken kesit türü / AWG hatlarında 24 ... 12

### Mekanik Tasarım

yükseklik	90 mm
genişlik	9 mm
derinlik	70 mm
net ağırlık	56 g
• işletim sırasında	-25 ... +55 °C
• depolama sırasında	-40 ... +75 °C

### Sertifikalar

General Product Approval	Declaration of Conformity	Test Certificates	Shipping Approval
 CCC	 UR	 VDE	 EG-Konf.
		<a href="#">Miscellaneous</a>	 LRS

other	Railway
<a href="#">Miscellaneous</a>	<a href="#">Vibration and Shock</a>

### Diğer bilgiler

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/tr/tr/Catalog/product?mlfb=5ST3020>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/tr/ps/5ST3020>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**



[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=5ST3020](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3020)

**CAX-Online-Generator**


<http://www.siemens.com/cax>

**Tender specifications**

<http://www.siemens.com/specifications>

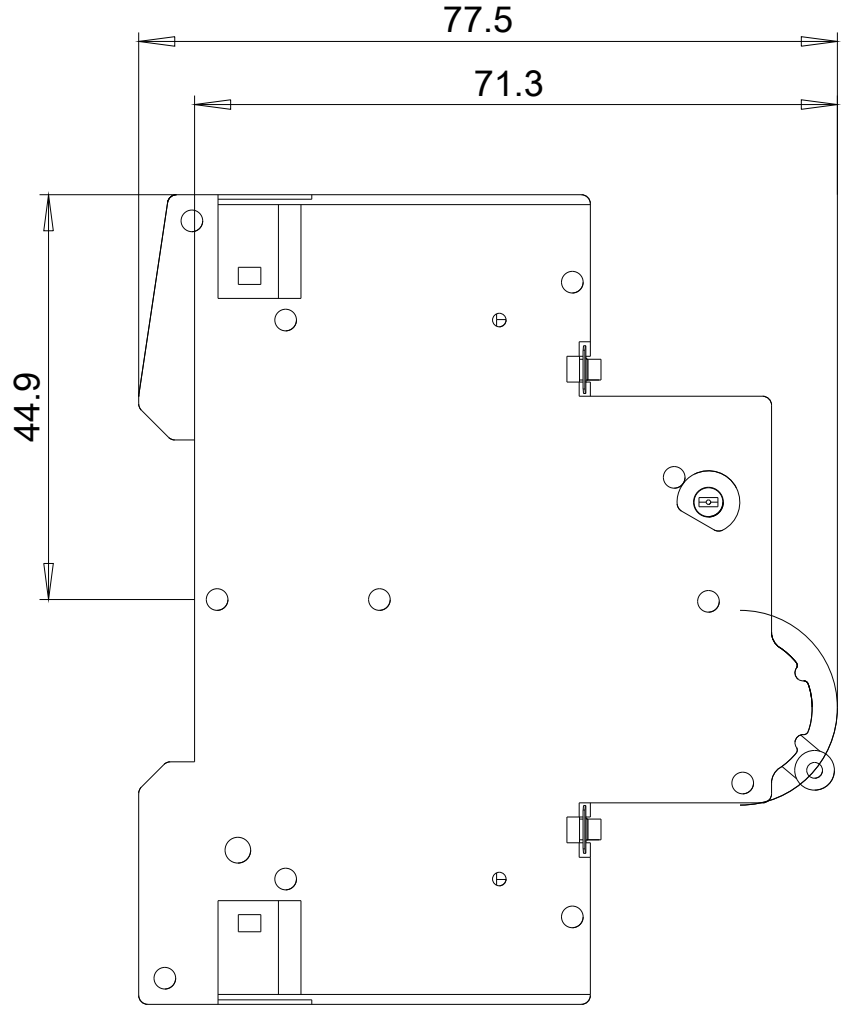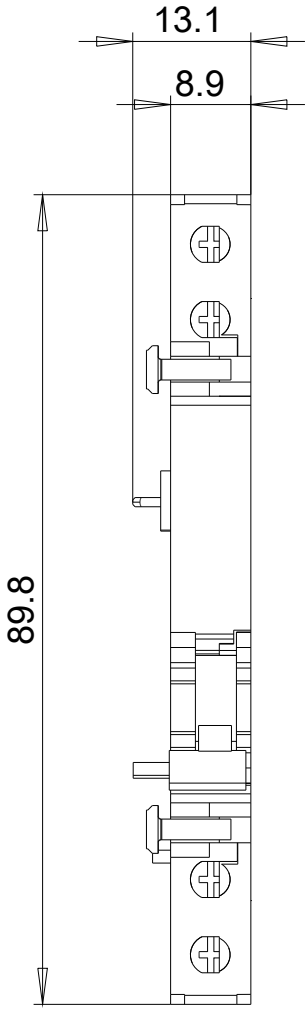

13 21

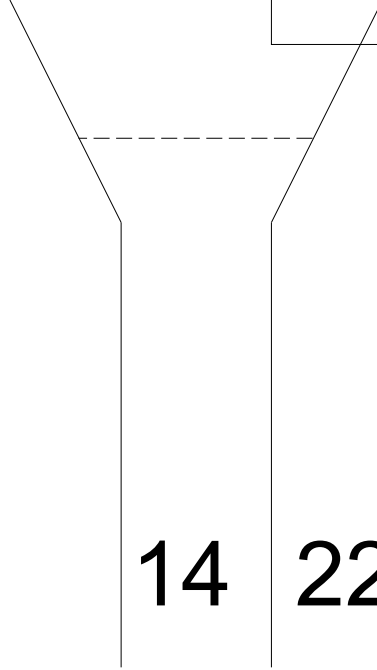

14 22

