

LV HRC fuse base Size 2L 400 A 1000 V for photovoltaic applications



Versiyon

ürün marka adı	SETRON
ürün tanımı	NH sigorta sistemi
yiv modeli / bağlantı vidası	M10
ürün modeli	NH alt parçaları 3NH

Genel teknik veriler

kutup sayısı	1
sigorta sistemi ebadı / DIN EN 60269-1 uyarınca	NH2L

Besleme gerilimi

akım / AC'de / anma değeri	400 A
besleme gerilimi	
• DC'de	1 000 V

Elektrik

Nominal sürekli akım I_n / IEC, DIN/VDE / 40 Cel'de	368 A
---	-------

Ürün Detayı

ürün bileşeni / içeri çevirme tertibatı	Evet
sınır kısa devre akımı kesme kapasitesi (Icu)	

- DC'de / anma değeri

25 kA

Bağlantılar

sıkma torku / vida bağlantısında	20 N·m
elektrik bağlantısı modeli	Montaj tablası üzerine montaj için yassı bağlantı
<ul style="list-style-type: none">• ana devre için	

Mekanik Tasarım

yükseklik	326 mm
genişlik	83 mm
derinlik	144 mm
sabitlenme türü	sabit monte
sabitlenme türü	
<ul style="list-style-type: none">• sürgülü montaj	Hayır
net ağırlık	1 724 g

Sertifikalar

referans işareti	
<ul style="list-style-type: none">• DIN EN 61346-2 uyarınca• IEC 81346-2:2009 uyarınca	F F

Diğer bilgiler

Information- and Downloadcenter (Catalogs, Brochures,...)

<http://www.siemens.com/lowvoltage/catalogs>

Industry Mall (Online ordering system)

<https://mall.industry.siemens.com/mall/tr/tr/Catalog/product?mlfb=3NH7360-4>

Service&Support (Manuals, Certificates, Characteristics, FAQs,...)

<https://support.industry.siemens.com/cs/ww/tr/ps/3NH7360-4>

Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)


http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NH7360-4

CAX-Online-Generator

<http://www.siemens.com/cax>

Tender specifications

<http://www.siemens.com/specifications>

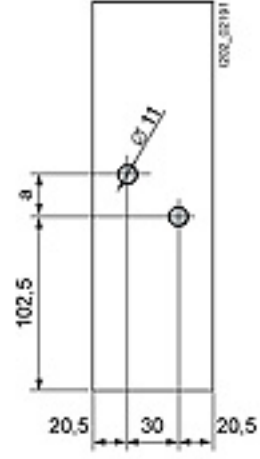

Size	Dim. a mm
1	25
1L	65
2L	65
3L	80
1XL	84
2XL	80