

LV HRC fuse element, NH0, In: 32 A, gG, Un AC: 500 V, Un DC: 440 V, Front indicator, live grip lugs



### Versiyon

ürün marka adı	SETRON
ürün tanımı	HRC sigorta buşonu
ürün modeli	Ölçüm cihazı kontaklı
gösterge sensörü modeli	Ön gösterge
anahtar kontak modeli	korozyona dayanıklı, gümüş kaplamalı
sigorta elemanı modeli	HRC sigorta buşonu

### Genel teknik veriler

sigorta sistemi ebadı / DIN EN 60269-1 uyarınca	NH0
sigorta soketinin çalışma sınıfı	gG
Güç şalteri / ana model	3NA3
montaj şekli	gerilim ileten tutamak kulakları
gerilim türü	AC
akım / AC'de / anma değeri	32 A
besleme gerilimi	
• AC'de / anma değeri	500 V

### Koruma sınıfı

IP koruma türü	IP20, bağlı ile...rle birlikte
----------------	--------------------------------



**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/tr/tr/Catalog/product?mlfb=3NA3012>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/tr/ps/3NA3012>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**



[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=3NA3012](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=3NA3012)

**CAX-Online-Generator**

<http://www.siemens.com/cax>


**Tender specifications**

<http://www.siemens.com/specifications>

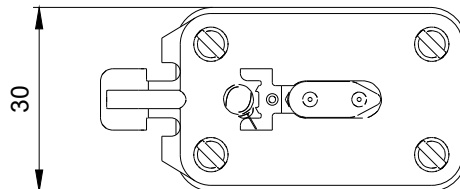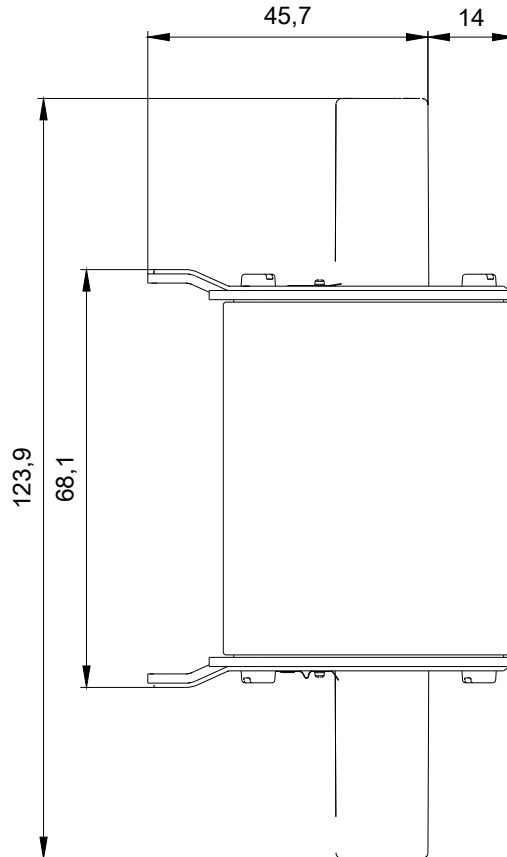

1

 -F1



2

