

Auxiliary current switch with test button 1 NO+1 NC for miniature circuit breaker 5SL, 5SY, 5SP Incorporated switch 5TL1, RCBO 5SU1 FI 5SV, for low power rating (for 5SU1 handle coupler 5ST3805-1 is required)



### Versiyon

ürün marka adı	SETRON
ürün tanımı	Yardımcı akım şalteri
ürün modeli	takılabilir
elektrikli işletim süresi (işletim çevrimleri) / tipik	20 000
IP koruma türü	IP20

### Ürün Detayı

ürün bileşeni	
• yardımcı anahtar	Evet
ürün ilavesi	Yardımcı şalter

### Numara

hata sinyali anahtarı sayısı	0
açıcı sayısı	1
kapayıcı sayısı	1
değiştirici sayısı	0

### Bağlantılar

bağlanabilir kablo kesiti	0,5 ... 2,5 mm <sup>2</sup>
sıkma torku / vida bağlantısında	0,5 N·m

bağlanabilir iletken kesit türü / AWG hatlarında	24 ... 12
--	-----------

## Mekanik Tasarım

yükseklik	90 mm
genişlik	9 mm
derinlik	70 mm
net ağırlık	45 g
• işletim sırasında	-25 ... +55 °C
• depolama sırasında	-40 ... +75 °C

## Sertifikalar

General Product Approval	Declaration of Conformity	Railway
--------------------------	---------------------------	---------



[Vibration and Shock](#)

## Diğer bilgiler

**Information- and Downloadcenter (Catalogs, Brochures,...)**

<http://www.siemens.com/lowvoltage/catalogs>

**Industry Mall (Online ordering system)**

<https://mall.industry.siemens.com/mall/tr/tr/Catalog/product?mlfb=5ST3013-2>

**Service&Support (Manuals, Certificates, Characteristics, FAQs,...)**

<https://support.industry.siemens.com/cs/ww/tr/ps/5ST3013-2>

**Image database (product images, 2D dimension drawings, 3D models, device circuit diagrams, ...)**



[http://www.automation.siemens.com/bilddb/cax\\_en.aspx?mlfb=5ST3013-2](http://www.automation.siemens.com/bilddb/cax_en.aspx?mlfb=5ST3013-2)

**CAX-Online-Generator**


<http://www.siemens.com/cax>

**Tender specifications**

<http://www.siemens.com/specifications>

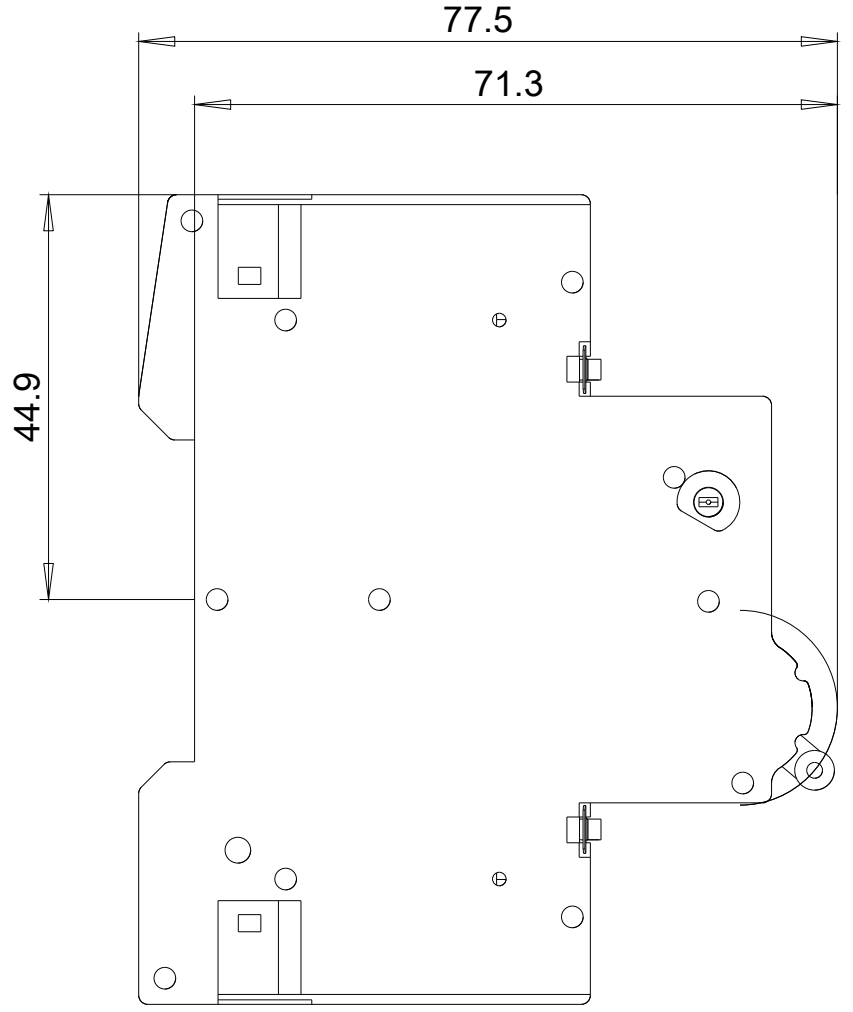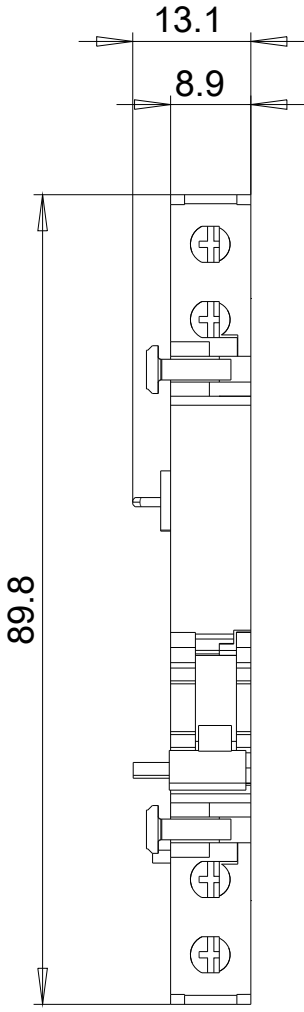

13 21

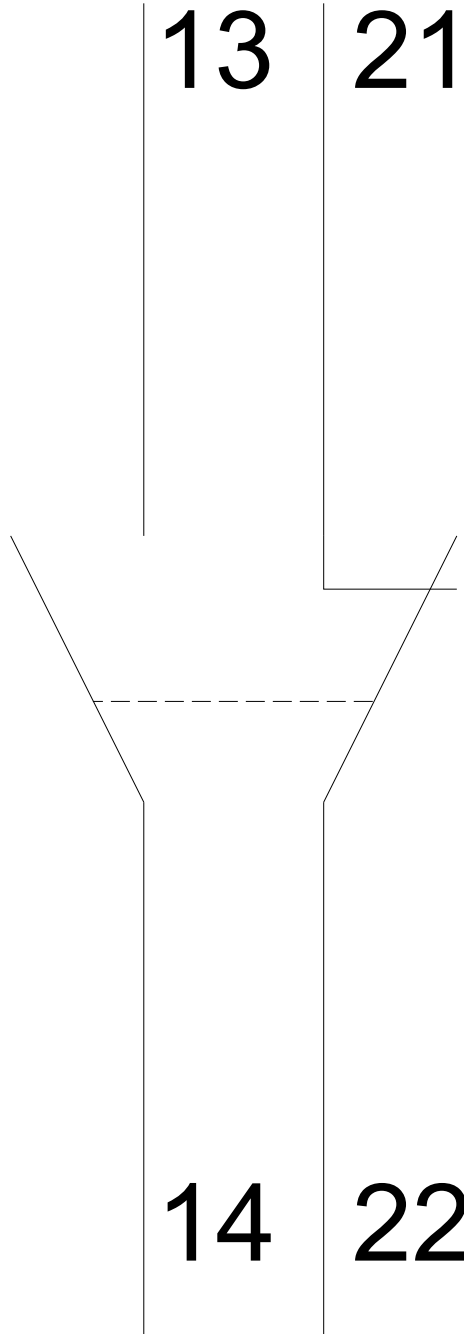

14 22

